



33.1±0.6

587(SCANNING WIDTH)

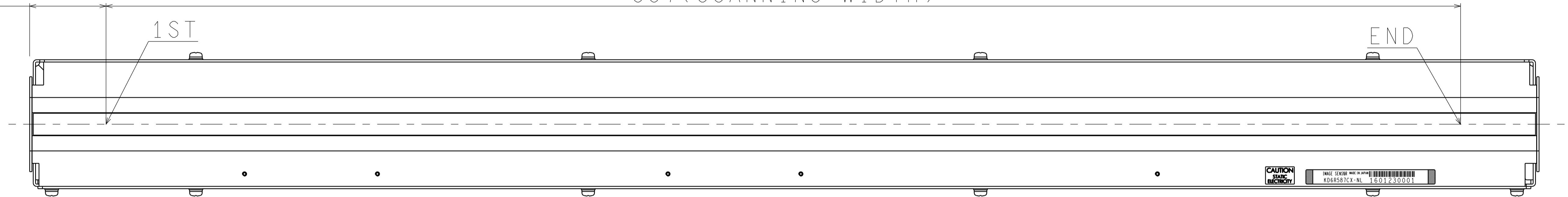

654.1±0.5

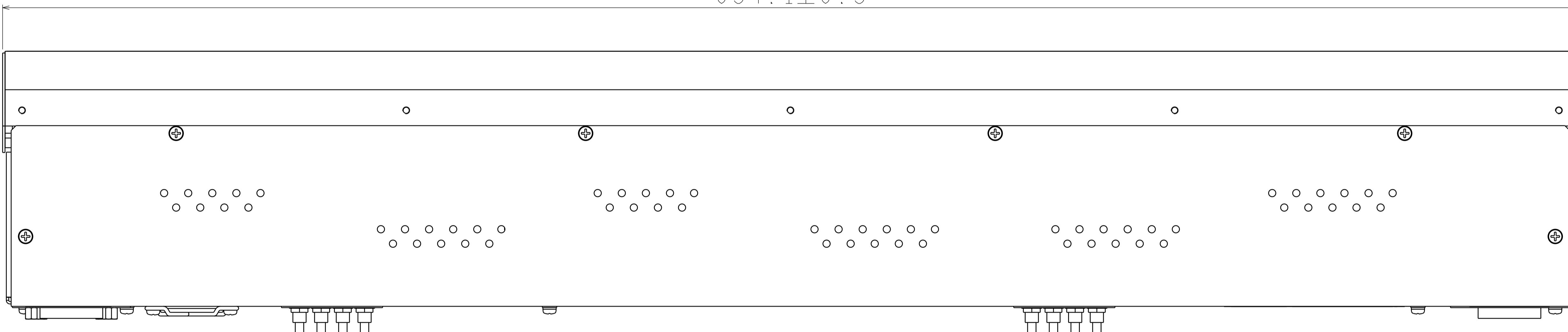

V1(DC5V IN)

(427.25)

(123.25)

(28.6)

(27)

(18)

(9)

D1-D4

V1

DC5V IN

L1

LED SIG OUT

(27)

(18)

(9)

D5-D8

V2

DC5V IN

V3

DC5V IN

L2

LED SIG OUT

(28.4)

L1(LED SIG OUT)

TM-XK882A KD6R587CX-NL QUTLINE

2020.7.27

Copyright(C)2020 MITSUBISHI ELECTRIC CORPORATION
ALL RIGHTS RESERVED.